

Technical data sheet Interconnection cable

Part no.: 50130488

KDS CR-SUB-9A-RJ41-A-T0-024-C

Contents

- Technical data
- Electrical connection

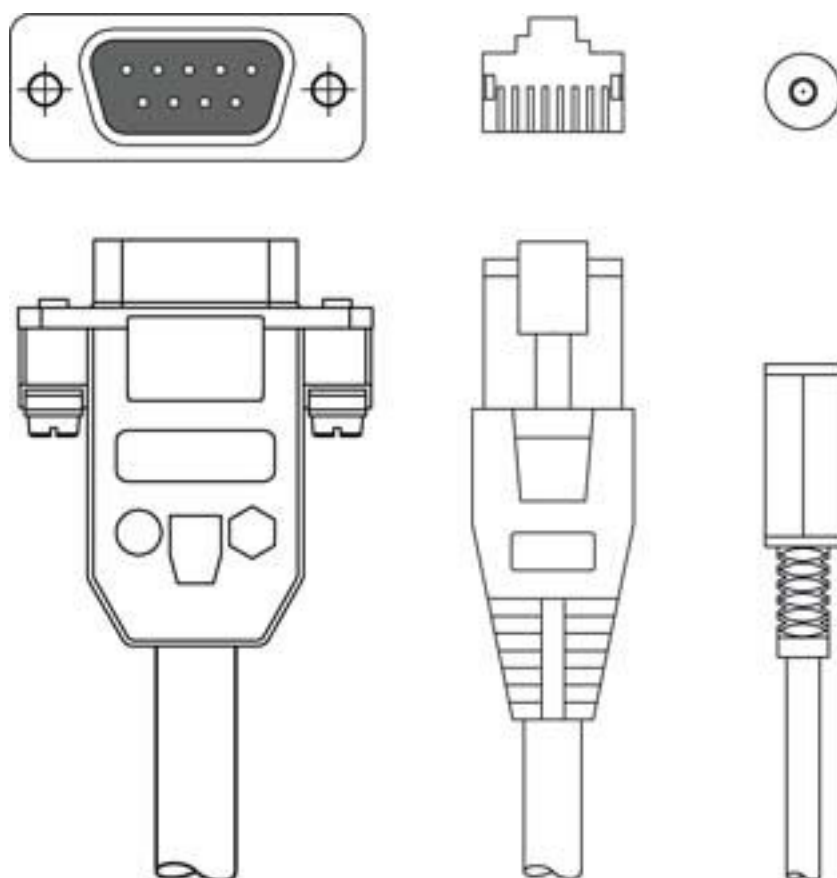


Figure can vary

Technical data

Basic data

Suitable for	HCR 6200 series mobile 2D-code readers
Suitable for interface	RS 232
	TTL

Connection

Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ41
--------------------	------

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial

Cable properties

Number of conductors	9 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	5 mm
Cable length	2,400 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

Electrical connection

Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ41
--------------------	------

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial