

Technical data sheet Signaling column element

Part no.: 50130437

E7-MW1

Contents

- Technical data
- Dimensioned drawings
- Electrical connection
- Notes



Figure can vary



Technical data

Basic data

Series	E7
--------	----

Connection

Connection 1

Type of connection	Terminal
Type of terminal	Tension spring technology

Mechanical data

Design	Cylindrical
Dimension (Ø x L)	70 mm x 81 mm
Housing material	Plastic
Housing color	Black
Design of mounting device	Bracket mounting
Type of fastening, at system	Screw type / vertical
Lens modules	Max. 5 pieces
Module holder	One side
Number of end caps	1 Piece(s)

Environmental data

Ambient temperature, operation	-30 ... 60 °C
--------------------------------	---------------

Certifications


Degree of protection	IP 66
----------------------	-------

Classification

Customs tariff number	85318070
eCl@ss 5.1.4	27371235
eCl@ss 8.0	27371235
eCl@ss 9.0	27371232
eCl@ss 10.0	27371235
eCl@ss 11.0	27371235
ETIM 5.0	EC001154
ETIM 6.0	EC001154
ETIM 7.0	EC001154

Dimensioned drawings

All dimensions in millimeters

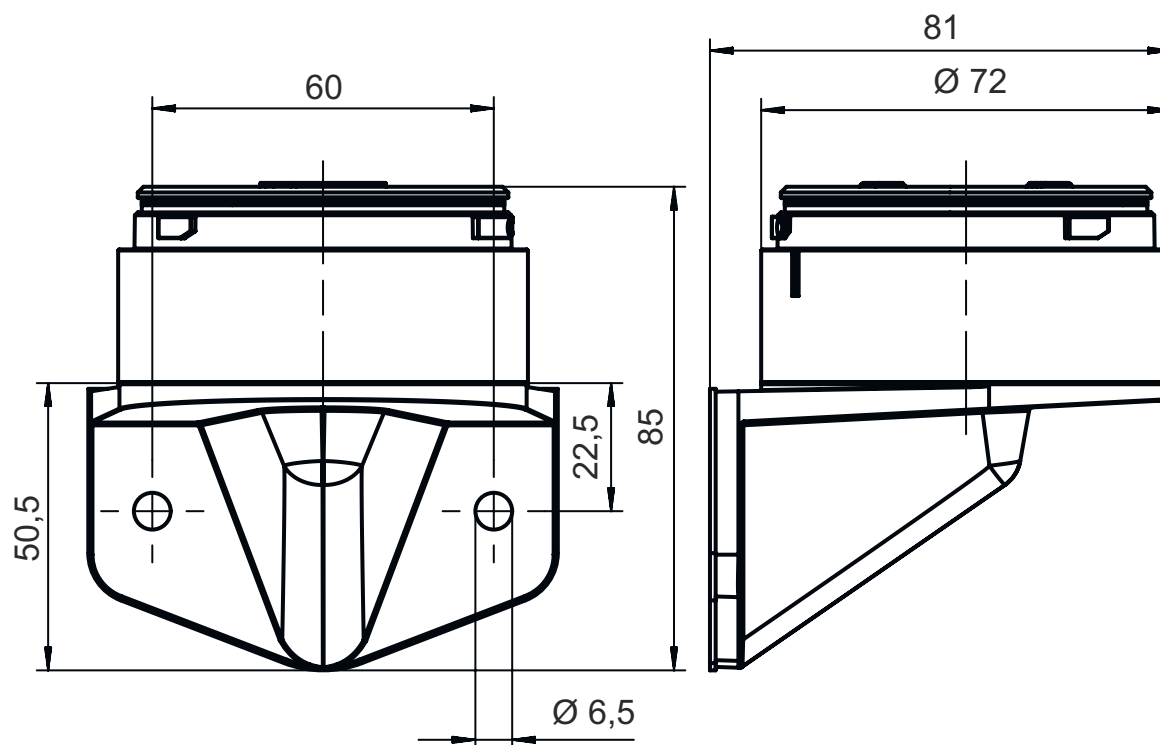

Electrical connection

Connection 1

Type of connection	Terminal
Type of terminal	Tension spring technology

Notes



Observe intended use!



- ⌘ This product is not a safety sensor and is not intended as personnel protection.
- ⌘ The product may only be put into operation by competent persons.
- ⌘ Only use the product in accordance with its intended use.



For UL applications:



- ⌘ For UL applications, use is only permitted in Class 2 circuits in accordance with the NEC (National Electric Code).