

## Technical data sheet

### Deflecting mirror

Part no.: 50110200

US 60-150W

#### Contents

- Technical data
- Dimensioned drawings
- Accessories



Figure can vary

## Technical data

### Basic data

Contains	2x M6 sliding block
Type, columns and mirrors	Surface deflecting mirror

### Mechanical data

Dimension (W x H x L)	25 mm x 68 mm x 220 mm
Net weight	600 g
Housing color	Yellow, RAL 1021
Type of fastening	Groove mounting Swivel mount
Suitable for sensor	Stationary bar code readers
Mirror length	210 mm
Mirror width	60 mm


### Classification

Customs tariff number	70099200
eCl@ss 5.1.4	27279207
eCl@ss 8.0	27279207
eCl@ss 9.0	27273605
eCl@ss 10.0	27273605
eCl@ss 11.0	27273605
ETIM 5.0	EC002467
ETIM 6.0	EC002467
ETIM 7.0	EC002467


## Dimensioned drawings

All dimensions in millimeters

### Mirror

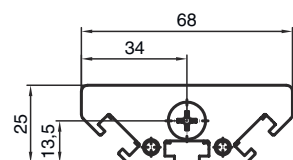


L Length = 220 mm  
SL Mirror length = 210 mm

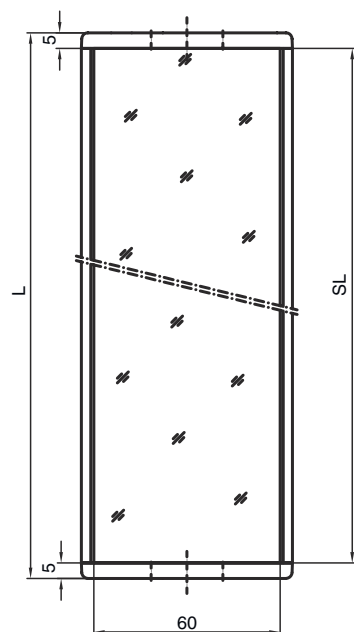


## Dimensioned drawings

### Mounting distances

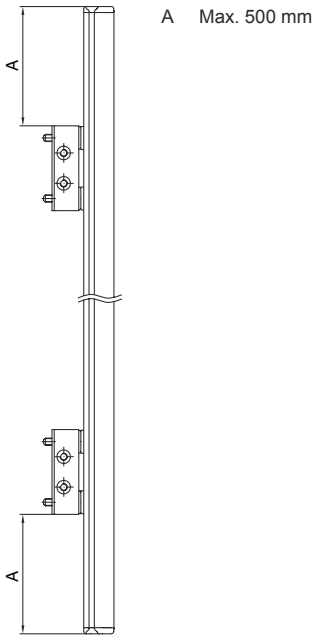




### Mounting with BT-2UM60 standard bracket

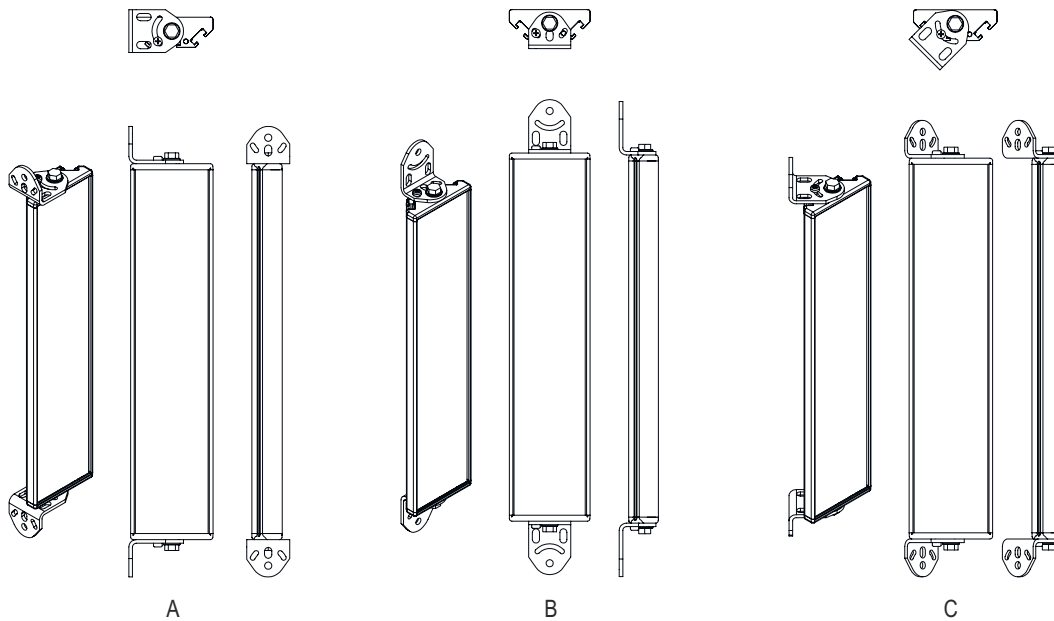


- A Lateral
- B Rear side
- C Adjustable at an angle (0 - 90°)

# Dimensioned drawings

  Mounting with BT-2SB10 swiveling mounting bracket

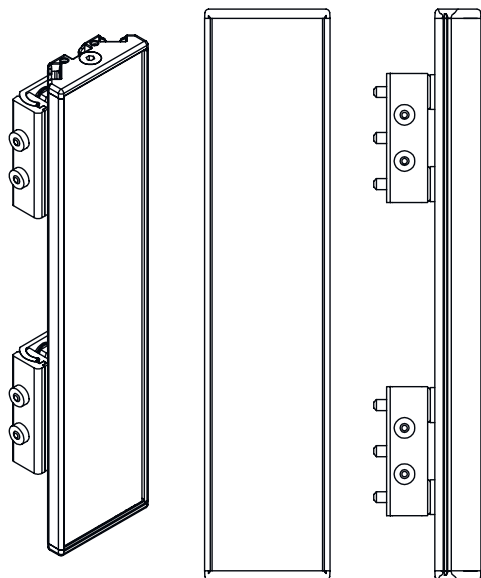

A

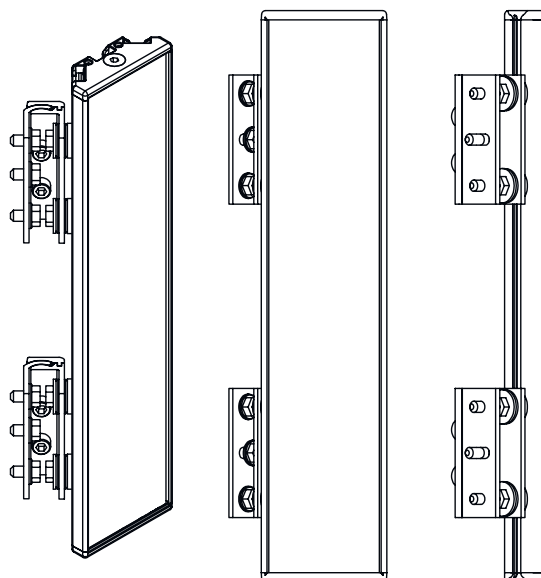



B

- A Rear side
- B Lateral 45°

## Accessories

### Mounting technology - Swivel mounts

	Part no.	Designation	Article	Description
	424422	BT-2SB10	Mounting bracket set	Design of mounting device: Mounting clamp Fastening, at system: Through-hole mounting Mounting bracket, at device: Clampable, On the lateral C-groove Type of mounting device: Swiveling Swivel range: -8 ... 8 ° Material: Metal
	430105	BT-2UM60	Mounting bracket	Fastening, at system: Through-hole mounting Mounting bracket, at device: Screw type Material: Metal

## Accessories

### Note



🔗 A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.