

## Technical data sheet Mobile bar code reader

Part no.: 50130504

IT 1450g 1D-2

### Contents

- Technical data
- Electrical connection
- Operation and display
- Accessories



Figure can vary



## Technical data

### Basic data

Series	IT145xg
--------	---------

### Read data

Code types, readable	2/5 Interleaved
	Codabar
	Codablock
	Code 128
	Code 39
	Code 93
	EAN 128
	EAN 8/13
	EAN Addendum
	GS1 Databar
	GS1 Databar Expanded
	GS1 Databar Limited
	GS1 Databar Omnidirectional
	GS1 Databar Stacked
	GS1 Databar Truncated
	UPC

### Optical data

Reading distance	37 ... 370 mm
Light source	LED
LED group	1
Camera resolution, horizontal	640 px
Camera resolution, vertical	480 px
Bar code contrast (PCS)	35 %
Modulus size	0.127 ... 0.508 mm

### Electrical data

#### Performance data

Supply voltage $U_B$	5 V, DC
Power consumption, max.	2 W

### Interface

Type	RS 232, USB
------	-------------

### RS 232

Function	Process
----------	---------

### USB

Function	Process
----------	---------

### Connection

#### Connection 1

Type of connection	RJ41
--------------------	------

### Mechanical data

Dimension (W x H x L)	62 mm x 169 mm x 82 mm
Housing material	Plastic, UL 94-V0
Net weight	130 g

### Environmental data

Ambient temperature, operation	0 ... 40 °C
Ambient temperature, storage	-40 ... 60 °C
Relative humidity (non-condensing)	0 ... 95 %
Drop height	1.5 m
Measurements relative to	Concrete floor

### Certifications

Degree of protection	IP 40
Certifications	c UL US

### Classification

Customs tariff number	84719000
eCl@ss 8.0	27280101
eCl@ss 9.0	27280101
ETIM 5.0	EC002550
ETIM 6.0	EC002550


## Electrical connection

### Connection 1

Function	Configuration interface Data interface Service interface
Type of connection	RJ41

### Pin Pin assignment

1	Shield
2	Cable ID
3	GND
4	TxD RS 232 / n.c. USB

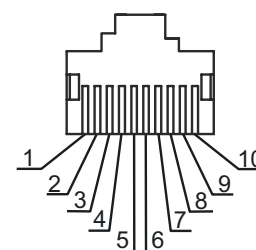

## Electrical connection


Pin	Pin assignment
5	RxD RS 232 / n.c. USB
6	CTS RS 232 / n.c. USB
7	+5 V DC
8	RTS RS 232 / n.c. USB
9	n.c. RS 232 / Data + USB
10	n.c. RS 232 / Data - USB

## Operation and display


LED	Display	Meaning
1	Green, 1x flashing	Reading successful
	Red	No reading result

## Accessories


### Connection technology - Connection unit

	Part no.	Designation	Article	Description
	50112891	MA 248i Profinet Gateway	Modular connection unit	Supply voltage: 18 ... 30 V Current consumption, max.: 300 mA Interface: PROFINET, RS 232 Connections: 6 Piece(s) Degree of protection: IP 65

### Connection technology - Interconnection cables


	Part no.	Designation	Article	Description
	50113397	KB JST-HS-300	Connection cable	Suitable for interface: RS 232 Connection 1: JST ZHR Connection 2: Sub-D, Axial, Male, 9 -pin Shielded: Yes Cable length: 300 mm Sheathing material: PUR

### Connection technology - Y distribution cables

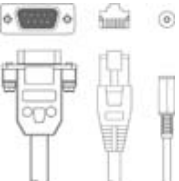	Part no.	Designation	Article	Description
	50114517	KB 232-1 IT190x	Interconnection cable	Suitable for interface: RS 232, TTL Connection 1: Sub-D, Axial, Female, 9 -pin Connection 2: RJ41 Connection 3: Connector, Pluggable, Axial, Female, 2 -pin Shielded: Yes Cable length: 3,000 mm Sheathing material: PVC

## Accessories

### Mounting technology - Other

	Part no.	Designation	Article	Description
	50120444	BT Wallholder HS65x8	Wall mount	Design of mounting device: Wall mounting Fastening, at system: Through-hole mounting Mounting bracket, at device: insertable Material: Plastic

#### Note



A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.