

Technical data sheet


Connection cable

Part no.: 50011952

BK7 KB-092-12000- 4 SE

Contents

- Technical data
- Electrical connection
- Circuit diagrams

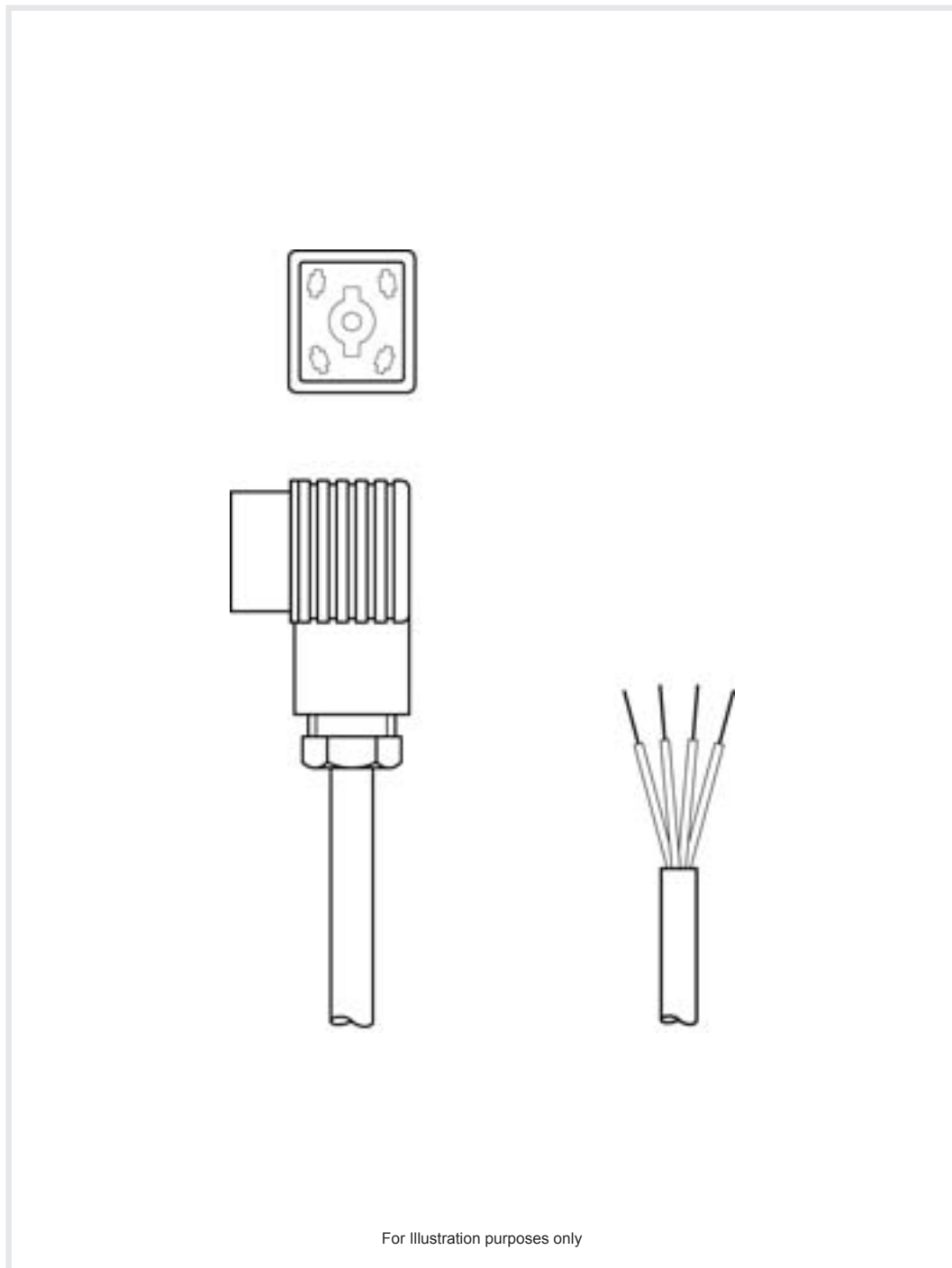

Technical data

Basic data

Application	Chemical resistant
-------------	--------------------

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	Standard plug
Connector, LED	No
No. of pins	4 -pin
Version	Angled
Type	Female

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	4.7 mm
Cable length	12,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Mechanical data

Net weight	377 g
------------	-------

Operation and display

Environmental data

Ambient temperature, operation	5 ... 40 °C
--------------------------------	-------------

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604

Electrical connection

Connection 1

Type of connection	Standard plug
Connector, LED	No
No. of pins	4 -pin
Version	Angled
Type	Female

Connection 2

Type of connection	Open end
--------------------	----------

Circuit diagrams

