

KFX-ETC7-120

Cod. art. 50117763

Fibra ottica, a tasteggio

KFX-ETC7-120

Part No. 50117763

Fiber, reflective

Dati tecnici

Tipo di fibra ottica	Coassiale
Temperatura operativa	-55°C ... +70°C
Raggio di curvatura min.	R15
Diametro esterno fibra ottica	2x Ø1,25mm
Diametro attivo fibra	1x Ø0,25mm 6x Ø0,25mm
Pezzo più piccolo riconoscibile	Ø0,05mm
Lunghezza totale	2019mm


Caratteristiche

Features



- 1) Impostazione di amplificatore per fibra ottica: max. tempo di reazione, max. amplificazione, min. soglia di commutazione / Adjustment on fiber optics amplifier: max. response time, max. gain, min. switching threshold

Disegno quotato/Dimensioned drawing

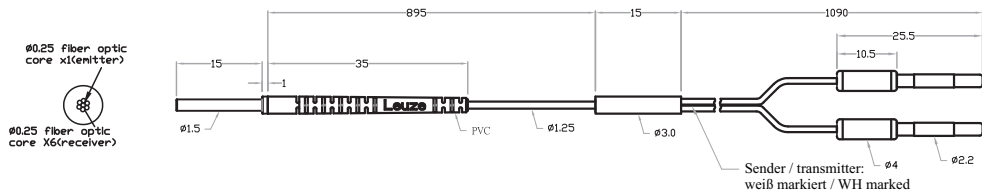

Specifications

Fiber type	Coaxial
Operating temperature	-55°C ... +70°C
Min. bending radius	R15
Fiber jacket diameter	2x Ø1.25mm
Active fiber diameter	1x Ø0.25mm 6x Ø0.25mm
Smallest detectable object	Ø0.05mm
Total length	2019mm

Portata limite tipica per oggetti chiari (bianco 90%) ¹⁾ Typ. scanning range limit for light objects (white 90%) ¹⁾

LV463I.XR	300mm
LV463.XR	150mm
LV463B, LV463.XV	105mm
LV463	60mm
LV462	35mm
LV461	20mm