

KFX-L-320

Cod. art. 50117770

Fibra ottica, unidirezionale

KFX-L-320

Part No. 50117770

Fiber, throughbeam

Dati tecnici

Tipo di fibra ottica	Standard
Temperatura operativa	-55°C ... +70°C
Raggio di curvatura min.	R25
Diametro esterno fibra ottica	Ø2,2mm
Diametro attivo fibra	Ø1,0mm
Pezzo più piccolo riconoscibile	Ø0,5mm
Lunghezza totale	2012mm
Unità d'imballo	2 pezzi


Caratteristiche

Features



- 1) Impostazione di amplificatore per fibra ottica: max. tempo di reazione, max. amplificazione, min. soglia di commutazione / Adjustment on fiber optics amplifier: max. response time, max. gain, min. switching threshold

Disegno quotato/Dimensioned drawing

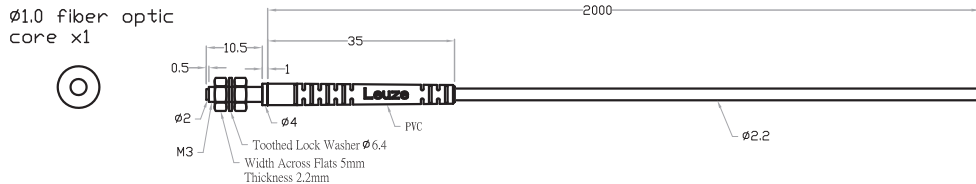

Specifications

Fiber type	Standard
Operating temperature	-55°C ... +70°C
Min. bending radius	R25
Fiber jacket diameter	Ø2.2mm
Active fiber diameter	Ø1.0mm
Smallest detectable object	Ø0.5mm
Total length	2012mm
Packaging unit	2 pieces

Portata limite tipica ¹⁾

Typ. scanning range limit ¹⁾

LV463I.XR	4500mm
LV463.XR	2250mm
LV463B, LV463.XV	1530mm
LV463	900mm
LV462	525mm
LV461	300mm