

KFX-LD-120
Cod. art. 50117777

**Fibra ottica,
unidirezionale**

KFX-LD-120
Part No. 50117777

fiber, throughbeam

Dati tecnici


Tipo di fibra ottica	Precisione
Temperatura operativa	-55°C ... +70°C
Raggio di curvatura min.	R15
Diametro esterno fibra ottica	Ø1,25mm
Diametro attivo fibra	Ø0,5mm
Pezzo più piccolo riconoscibile	Ø0,05mm
Lunghezza totale	2015mm
Unità d'imballo	2 pezzi

Caratteristiche Features



- 1) Impostazione di amplificatore per fibra ottica: max. tempo di reazione, max. amplificazione, min. soglia di commutazione / Adjustment on fiber optics amplifier: max. response time, max. gain, min. switching threshold

Disegno quotato/Dimensioned drawing

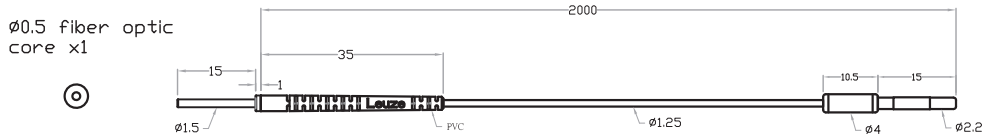

Specifications

Fiber type	Precision
Operating temperature	-55°C ... +70°C
Min. bending radius	R15
Fiber jacket diameter	Ø1.25mm
Active fiber diameter	Ø0.5mm
Smallest detectable object	Ø0.05mm
Total length	2015mm
Packaging unit	2 pieces

Portata limite tipica ¹⁾ Typ. scanning range limit ¹⁾

LV463I.XR	1500mm
LV463.XR	750mm
LV463B, LV463.XV	510mm
LV463	300mm
LV462	175mm
LV461	100mm